



vulcan[®] 202


Key performance

- High scrolling and high mechanical resistance
- Designed with **Feed-0 Technology**:
 - Optimum paper feed tension
 - Reduced risks of paper breaks
 - Easier control of colour register during the start-up
 - Improved paper wastage control

MAIN APPLICATION

Heatset, Coldset

**Vulcan 202 is available in 4-ply,
1,95 mm thickness.**

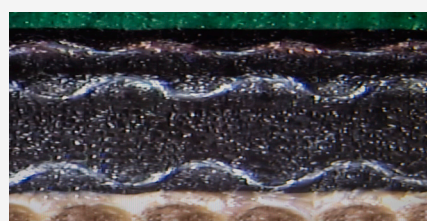

Vulcan 202

✓ The product at a glance

INK COMPATIBILITY	Hybrid
THICKNESS (mm)	1.95
PRINTING SURFACE COLOUR	Green
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Neutral
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>70
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
NEW TECHNOLOGY	Feed-0

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**