

vulcan[®] DUO


Key performance

- Unique blanket design
- Improved Smash resistance and high durability
- Reduced edge mark
- Very flexible for an easy mounting on press
- Suitable for hybrid printing
- Dedicated for packaging and commercial sheetfed

MAIN APPLICATION

Commercial Sheetfed,
Packaging

**Vulcan DUO is available in 2-ply,
1,95 mm thickness.**

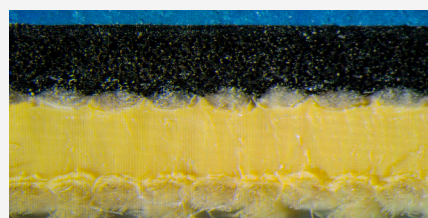

Vulcan Duo



The product at a glance

INK COMPATIBILITY	Hybrid
THICKNESS (mm)	1.95
PRINTING SURFACE COLOUR	Blue
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<1,1
TENSILE STRENGTHS (N/mm)	>140
ADDITIONAL INFORMATION	
APPLICATIONS	Commercial Sheetfed and Packaging

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**