


Key performance

- Suitable for high speed newspaper presses
- Positive paper feed
- Implements all benefits of the **Dynatech System**:
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

Sheetfed, Packaging

Vulcan Folio is available in 3 ply, 1,95 mm thickness.

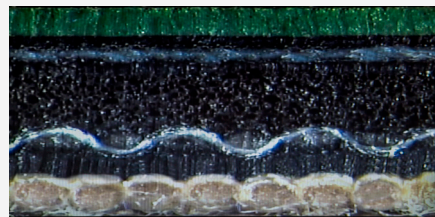

Vulcan Folio



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Green
THICKNESS (mm)	1,95
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	230
SURFACE ROUGHNESS (Ra micron)	0,6
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	Yes
NEW TECHNOLOGY	Dynatech
ADDITIONAL INFORMATION	
APPLICATIONS	The EPDM top face for UV inks is available (Folio UV)

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**