



vulcan[®] Eco


Key performance

- Specifically designed for a wide range of applications in sheetfed printing and in metal decorating
- Suitable for high volumes printing
- Improved printing quality in tough conditions

MAIN APPLICATION

Commercial Sheetfed

Vulcan Eco is available in 4 ply, 1,95 mm thickness.

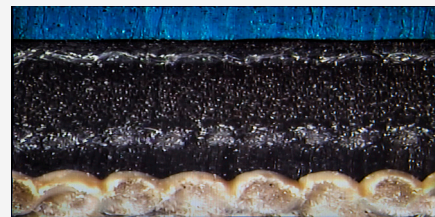

Vulcan Eco

✓ The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,95
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	260
SURFACE ROUGHNESS (Ra micron)	1,0
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	Vulcan print quality on a variety of stocks

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**