




Key performance

- Suitable for high speed newspaper presses
- Positive paper feed
- Implements all benefits of the **Dynatech System**:
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

Commercial Sheetfed

Vulcan Folio is available in 3 ply,
1,95 mm thickness

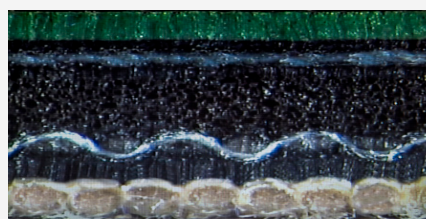

Vulcan Folio



The product at a glance

| | |
|--|---|
| INK COMPATIBILITY | Hybrid |
| PRINTING SURFACE COLOUR | Green |
| THICKNESS(mm) | 1,95 |
| AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation | 250 |
| SURFACE ROUGHNESS (Ra micron) | 0,6 |
| ELONGATION (%) | <0,9 |
| TENSILE STRENGTH (N/mm) | >67 |
| WATER & SOLVENT PROTECTION | Yes |
| ADVANCED TECHNOLOGY | Dynatech |
| ADDITIONAL INFORMATION | |
| MORE VERSIONS | The EPDM top face for UV inks is available (Folio UV) |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**