



vulcan® Sunrise

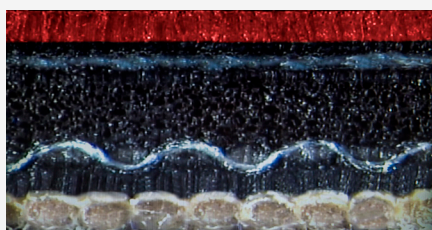
Key performance

- Specifically designed for the latest UV applications (LE/HUV, LED UV)
- Excellent printing quality (solids and half tone reproduction)
- Very good ink release
- Avoid ink back-trapping
- Implements all benefits of the **Dynatech System:**
 - Excellent smash and edge marks resistance
 - Better vibration absorption

MAIN APPLICATION

UV

Vulcan Sunrise is available in 3 ply, 1,96 mm thickness.

Vulcan Sunrise

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Red
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	230
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	Dynatech System

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**