

Printec® 334


Key Performance

- Specifically designed for UV applications
- Extremely resistant to swelling and embossing from UV inks and blanket washes
- High printing quality
- High degree of smash resistance, thus less blanket changes
- Suitable also for packaging applications (printing on paper and cardboard)

MAIN APPLICATION

Sheetfed, Packaging

Printec 334 is available in 3 ply (1,96/1,98 mm) thickness

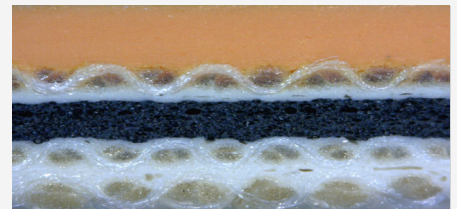

Printec 334

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Orange
THICKNESS (mm)	1,96/1.98
AVERAGE LOAD VALUE N/cm² @ 0,20 mm Indentation	140
SURFACE ROUGHNESS (Ra micron)	1,0
ELONGATION (%)	< 2
TENSILE STRENGTHS (kgf/cm)	> 58
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	Sheetfed and Packaging

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printing@trelleborg.com**

Printec® 8263

Key Performance

- Self-adhesive blanket specifically designed for 2-piece can printing
- The laser engraved blanket ensures high and reliable printing
- The advanced acrylic adhesive provides strong adhesion
- Printec 8263 can be easily removed from the cylinder
- The mechanical resistance is extremely high
- The top face can be laser engraved with extreme precision
- Unique feature: cream color of the layer under the top face allows a better control of the engraved design


MAIN APPLICATION

2-piece can

**Printec 8263 is available in 3 ply
(1,97 mm) thickness**



Printec 8263 laser engraved

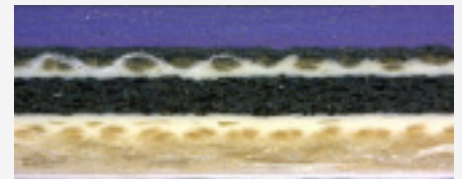

Printec 263

✓ The product at a glance

PRINTEC	8263 laser engraved	263
INK COMPATIBILITY	Conventional	Conventional
PRINTING SURFACE COLOUR	Purple	Purple
THICKNESS (mm)	1,97	1,97
TOP THICKNESS (mm)	0,6	0,5
AVERAGE LOAD VALUE N/cm ² @ 0,20 mm Indentation	115	115
SURFACE ROUGHNESS (µm)	1,0	1,0
TENSILE STRENGTHS (kgf/cm)	> 30	> 30
ADDITIONAL INFORMATION		
UNIQUE FEATURE	Cream color of the layer to better control the engraved design	-

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**

www.trelleborg.com/printing

The information contained in this document is intended to provide guidance. The information is NOT a specification and all figures in the document are nominal. This document and the information it contains do not create any warranties for any product and Trelleborg Printing Solutions disclaims any warranty of merchantability or fitness for a particular purpose for the product described in this document. This document discloses information that is proprietary to Trelleborg Printing Solutions. The receipt or possession of the document does not confer any right to reproduce or disclose the document, any information contained in it, or any physical article or device, or to practice any method or process except by written agreement with Trelleborg Printing Solutions. Trelleborg Printing Solutions is committed to the ongoing development of its products. For that reason, Trelleborg Printing Solutions reserves the right to alter the actual specifications of its products without prior notice.