

# ADVANTAGE PLUS

## Sheetfed blanket

The range of the ADVANTAGE offset printing blankets is noted for outstanding dimensional stability, minimum loss in thickness, impact resistance, longer service life and excellent print quality. Designed and formulated for a wide range of sheetfed presses for printing on paper/carton stocks.

<b>COLOUR</b>	Blue
<b>CONSTRUCTION TYPE</b>	Cord Carcass Compressible
<b>SURFACE FINISH</b>	Ground and polished
<b>MICRO HARDNESS</b>	65 +/- 3 IRHD
<b>STRETCH</b>	< 0.70% @ 500 N/5 cm
<b>NOMINAL THICKNESS</b>	1.95 mm (ISO 12636) 1.70 mm (ISO 12636)
<b>BOTTOM LAYER</b>	Water/Solvent sealed
<b>PACKING &amp; TENSIONING</b>	Conform to OEM instructions


### APPLICATION

- Sheetfed
- Heatset
- Coldset
- Packaging
- Coating
- Metal
- Continuous F.

### INK

- UV
- Conventional
- Hybrid

### STRUCTURE

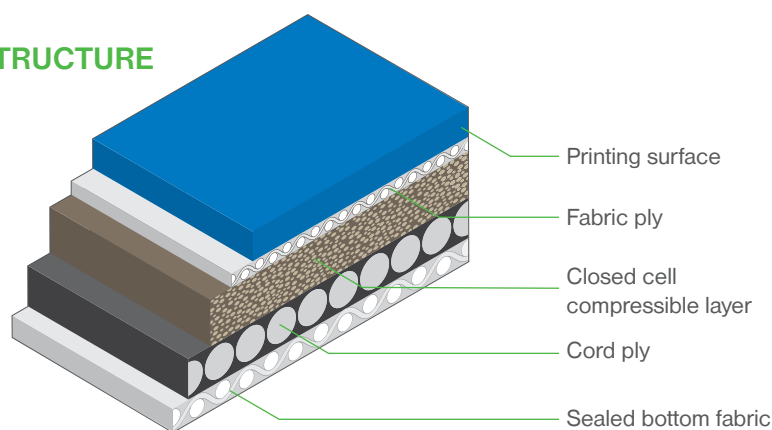

● Recommended ● Suitable ● Not recommended

### CHARACTERISTICS

#### Dimensional Stability

### ADVANTAGES

Virtually no sinking or stretching giving the blanket an exceptional dimensional stability. After mounting no need for further re-tensioning thus leading to a reduced down time.

#### Closed Cell Compressible Layer

New compressible layer coupled with a radial cord carcass improves durability, offers excellent shock absorption and rapid recovery. Resists solvent penetration, reduces the risk of delamination.

#### Microground Printing Surface

The specially formulated surface compound is specifically ground in order to ensure excellent ink transfer and dot reproduction on a wide range of paper/carton qualities.

#### Sealed Bottom Layer

Provides added protection against water and chemical penetration.