



Printec 700


Key performance

- Suitable for web heatset applications
- Long blanket lifetime
- Calibrated thickness with minimal relevance
- Positive paper feed

MAIN APPLICATION

Heatset, Coldset

Printec 700 is available in 3-4ply, 1,71-1,96 mm thickness

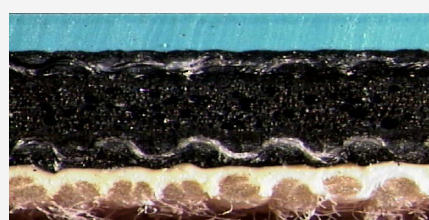

Printec 700

✓ The product at a glance

INK COMPATIBILITY	Conventional
PRINTING SURFACE COLOUR	Light Blue
THICKNESS (mm)	1,71-1,96
AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Positive
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
BLANKET CONSTRUCTION	The micro ground surface combined with a robust carcass construction results in a calibrated blanket thickness with a minimal relevance.

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**