

Corrugated Pipe Adapter

Corrugated Pipe Adapter




Provides a good sealing surface on corrugated HDPE pipe

Easy to install – Simply stretch it over the pipe to the desired location

Certified to ASTM C923 when used with a Kor-N-Seal® Connector

Specifically designed for use with most sizes of ADS, Hancor, Lane, N-Flow, Quality Culvert, JM Eagle and Contech A2000

The unique design of our Pipe Adapter distributes the force from the pipe clamp on our Kor-N-Seal connector directly against the inside walls of the pipe corrugations, creating a watertight seal up to 24 inches*.

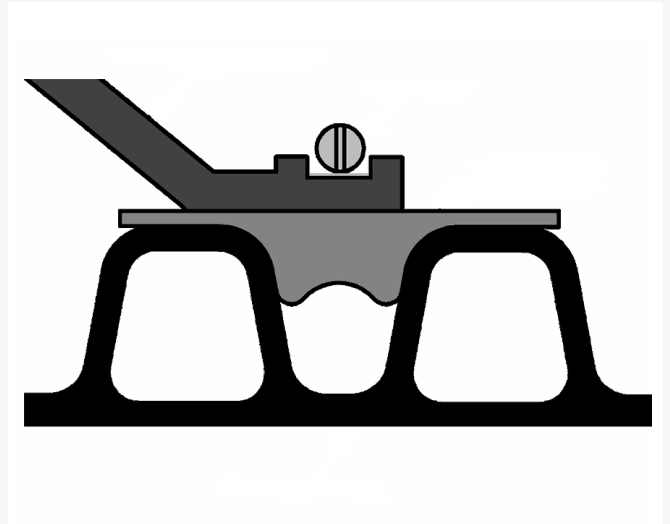

CORRUGATED PIPE ADAPTER

Pipe Size (inches)	Pipe Mfg.	Pipe O.D. Ref. + 1/4 (inches)	Adapter Part No.	Kor-N-Seal Connector	Sealing Capability	
8	ADS	9 1/8	CGA-8A	S106-12 or S406-12	WT	
	Hancor	9 1/8	CGA-8H		WT	
	Lane	9 7/16	CGA-8L		WT	
10	ADS	11 3/8	CGA-10A	S106-16A	WT	
	Hancor	11 3/8	CGA-10H		WT	
	Lane	11 3/4	CGA-10L		WT	
12	ADS	14 3/8	CGA-12A	S106-16T or S106-20BW	WT	
	Hancor	14 3/8	CGA-12H		WT	
	Lane	14 9/16	CGA-12L	S106-20BW	WT	
	JM Eagle	14 1/4	CGA-12JM		ST	
	Quality Culvert	14 1/2	CGA-12Q		ST	
	Baughman	14 1/2	CGA-12B		ST	
	N-Flow	15	CGA-12N		ST	
	Contech A2000	12 3/4	CGA-12C		S106-16A	WT
15	ADS	17 1/2	CGA-15A	S106-20W, S206-20L	WT	
	Hancor	17 1/2	CGA-15H		WT	
	Lane	17 7/16	CGA-15L		WT	
	Baughman	18 1/4	CGA-15B	S206-22 or S206-24A	ST	
	N-Flow	18	CGA-15N		ST	
	Quality Culvert	17 1/2	CGA-15Q	S106-20W, S206-20L	ST	
	JM Eagle	17 1/2	CGA-15JM		ST	
	Contech A2000	15 5/8	CGA-15C	S106-20AW	WT	
18	ADS	21 3/16	CGA-18A	S206-24L, S306-24L	WT	
	Hancor	21 3/16	CGA-18H		WT	
	Lane	21 3/16	CGA-18L		WT	
	Baughman	21 4/19	CGA-18B		ST	
	N-Flow	21	CGA-18N		ST	
	Quality Culvert	21 5/16	CGA-18Q		ST	
	Contech A2000	19 1/4	CGA-18C	S206-22L, S306-22L or S206-24A	WT	
	JM Eagle	20 7/8	CGA-18JM	S206-24	WT	
21	Contech A2000	22 9/16	CGA-21C	S206-26, S306-26	WT	
24	ADS	27 3/4	CGA-24A	S206-30L-32, S306-30L-32	WT	
	Hancor	27 3/4	CGA-24H		WT	
	Lane	28	CGA-24L	S206-32, S306-32	WT	
	Baughman	28 1/2	CGA-24B		ST	
	N-Flow	28	CGA-24N		ST	
	Quality Culvert	27 15/16	CGA-24Q		S206-30L-32, S306-30L-32	ST
	Contech A2000	25 1/2	CGA-24C		S206-28L, S306-28L	WT
JM Eagle	27 1/2	CGA-24JM	S206-30L	ST		

Pipe Size (inches)	Pipe Mfg.	Pipe O.D. Ref. + 1/4 (inches)	Adapter Part No.	Kor-N-Seal Connector	Sealing Capability	
30	ADS	35	CGA-30A	S206-38L, S306-38L-STORM, S306-38LS-PG	ST	
	Hancor	36	CGA-30H	S206-40, S306-40-STORM	ST	
	N-Flow	35	CGA-30N	S206-38L, S306-38L-STORM	ST	
	Baughman	35 13/20	CGA-30B	S206-40, S306-40-STORM	ST	
	Quality Culvert	34 7/8	CGA-30Q	S206-38, S306-38L-STORM	ST	
	Lane	34 3/4	CGA-30L		ST	
	Contech A2000	32 3/16	CGA-30C	S206-36, S306-36-STORM	ST	
	JM Eagle	34 5/8	CGA-30JM	S206-38, S-306-38-STORM	ST	
	36	ADS	41 7/8	CGA-36A	S206-44L-46, S306-44L-46, S306-44LS-PG	ST
		Hancor	41 3/8	CGA-36H		ST
Lane		40 7/8	CGA-36L	ST		
Baughman		41 1/2	CGA-36B	S206-44L, S306-44L-STORM	ST	
N-Flow		41 1/8	CGA-36N		ST	
Quality Culvert		41 3/8	CGA-36Q		ST	
Contech A2000		38 3/4	CGA-36C		S206-42L, S306-42L-STORM	ST
JM Eagle		41 1/2	CGA-36JM		S206-44L	ST
42	ADS	47 11/16	CGA-42A	S206-52L	ST	
	Hancor	47 15/16	CGA-42H		ST	
	Baughman	48 1/5	CGA-42B		ST	
	N-Flow	48	CGA-42N		ST	
	Quality Culvert	48 1/4	CGA-42Q		ST	
	Lane	47 3/8	CGA-42L		S206-52	ST
	JM Eagle	47 3/8	CGA-42JM	ST		
48	ADS	53 7/16	CGA-48A	S206-58L	ST	
	Hancor	53 11/16	CGA-48H		ST	
	Lane	54	CGA-48L		ST	
	Baughman	54 3/10	CGA-48B		ST	
	N-Flow	54	CGA-48N		ST	
	Quality Culvert	54 3/4	CGA-48Q		ST	
54	JM Eagle	53 13/16	CGA-48JM	S206-58	ST	
	Hancor	60 15/16	CGA-54H	S206-64L, S206-66	ST	
60	ADS	66 1/4	CGA-60A	S206-70L	ST	
	Hancor	67 3/16	CGA-60H	S206-72	ST	

WT = Watertight ST = Soiltight

Covered under U.S. Patent No. 6,364,373



TRELLEBORG

WWW.TRELLEBORG.COM/PIPE-SEALS