



# Kor-N-Seal® I Slotted Band Series

## Slotted Band Series



Easy to install

Installed from outside of the manhole

Meets the specifications of ASTM C923


Integral combination ratchet/torque limiter for accurate and reliable installation

Available with Hydraulic installation tool


Patented Waveband technology creates a more effective seal by concentrating the compressive force of the expansion band. The rubber is "captured" between the band and the concrete.



| Kor-N-Seal Connector P/N | Suggested Pipe O.D. Range (inches) | Hole Size Range (inches) | Connector Dimensions (inches) |       |   | Pipe Clamp P/N |
|--------------------------|------------------------------------|--------------------------|-------------------------------|-------|---|----------------|
|                          |                                    | A                        | B                             | C     | D |                |
| S406-11BSL               | 6.00 - 7.00                        | 11.00 - 11.25            | 9.625                         | 6.50  | 6 | I-128          |
| S406-11ASL               | 7.50 - 9.00                        | 11.00 - 11.25            | 9.625                         | 8.50  | 6 | I-128          |
| S406-12CSL               | 6.00 - 7.00                        | 12.00 - 12.25            | 10.625                        | 6.50  | 6 | I-128          |
| S406-12BSL               | 6.25-7.50                          | 12.00 - 12.25            | 10.625                        | 7.00  | 6 | I-128          |
| S406-12ASL               | 7.50-9.00                          | 12.00 - 12.25            | 10.625                        | 8.50  | 6 | I-180          |
| S406-12SL                | 9.00-10.50                         | 12.00 - 12.25            | 10.625                        | 10.00 | 6 | I-180          |

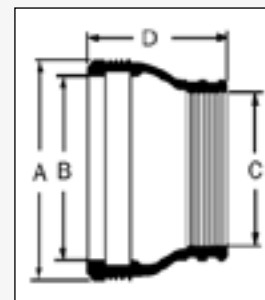

| Kor-N-Seal Connector P/N | Suggested Pipe O.D. Range (inches) | Hole Size Range (inches) | Connector Dimensions (inches) |       |   | Pipe Clamp P/N |
|--------------------------|------------------------------------|--------------------------|-------------------------------|-------|---|----------------|
|                          |                                    | A                        | B                             | C     | D |                |
| S106-12BSL               | 5.75 - 7.00                        | 12.00 - 12.25            | 10.625                        | 6.50  | 8 | I-128          |
| S106-12ASL               | 7.00 - 8.50                        | 12.00 - 12.25            | 10.625                        | 8.00  | 8 | I-180          |
| S106-12SL                | 8.25 - 9.75                        | 12.00 - 12.25            | 10.625                        | 9.25  | 8 | I-180          |
| S106-14ASL               | 9.50-11.25                         | 14.00 - 14.25            | 12.625                        | 10.50 | 8 | I-190          |
| S106-16BSL               | 9.50-11.25                         | 15.95 - 16.20            | 14.625                        | 10.50 | 8 | I-190          |
| S106-16ASL               | 11.25-13.00                        | 15.95 - 16.20            | 14.625                        | 12.25 | 8 | I-218          |
| S106-16SL                | 13.00-14.20                        | 15.95 - 16.20            | 14.625                        | 14.00 | 8 | I-242          |

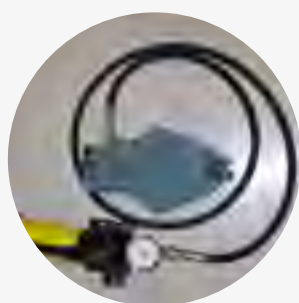

Hydraulic Installation Tool



**TRELLEBORG**

[WWW.TRELLEBORG.COM/PIPE-SEALS](http://WWW.TRELLEBORG.COM/PIPE-SEALS)