



Brawler HPS Tough jobs, soft ride.



**SOFT
RIDE**

Maximum comfort
and durability



Download the App for free



Tire iBrochure


Protecting people protecting assets.

Delivering the smoothest ride in the Brawler range, Trelleborg's Brawler HPS Soft Ride tires are designed to perform in tough recycling and waste management applications. The Soft Ride compound combined with Brawler's unique elliptical sidewall apertures

delivers higher shock absorption and reduced vibration, ensuring the best possible protection for operators and machines. Brawler HPS Soft Ride offers both the toughness of a traditional solid tire and the ride comfort of a filled pneumatic tire.


Vibration & Comfort – Dynamic Test

TESTED TO ISO 5008

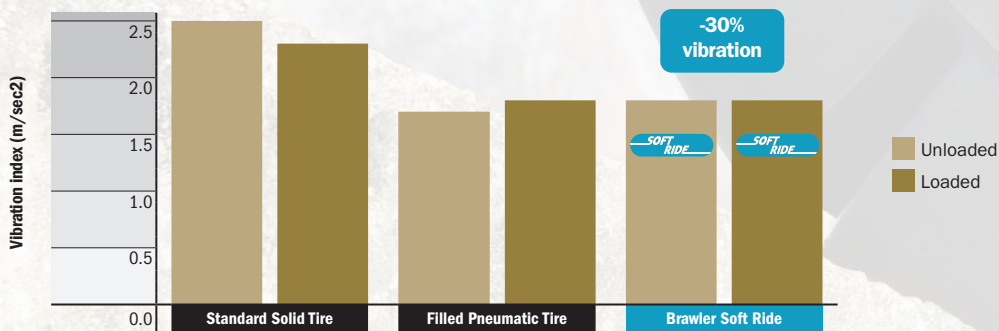

Deflection – Static Test

DEFORMATION (MM) UNDER VARIABLE LOAD

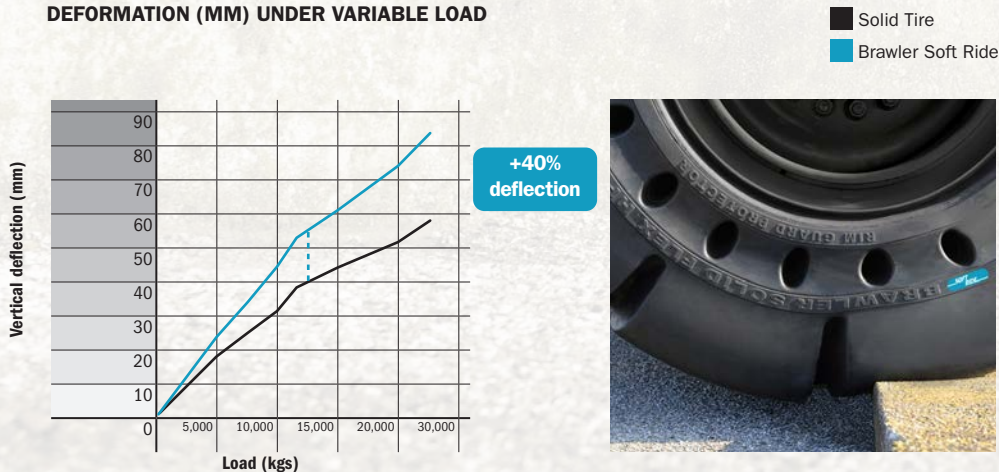

Brawler HPS Soft Ride.

**SOFT
RIDE**



**ANTI VIBRATION
CONSTRUCTION**
Enhanced driver comfort



**CUT RESISTANT
COMPOUND**
Damage protection



ELLIPTICAL APERTURES
Increased deflection



ULTRA DEEP TREAD
Extended service life

Why choose Soft Ride?



MAXIMUM VALUE
Reduced operating cost per hour



MAXIMUM UPTIME
Increased productivity, maintenance free



INCREASED SAFETY
Reduced driver exposure to vibration



REDUCED IMPACT
Protecting people, protecting assets

Brawler HPS Soft Ride

PREMIUM OTR SOLID



HPS SOLIDFLEX TRACTION

Tire Size	Alternative Size	Rim Size	Overall Diameter [mm]	Section Width [mm]	Tread Depth [mm]	Load Capacity 10 km/h [kg]
17.5-25 *	445/80-25	14.0-25	1,340	446	155	8,805
20.5-25 *	525/80-25	17.0-25	1,495	527	188	12,155
23.5-25 *	605/80-25	19.5-25	1,630	606	216	15,320
26.5-25 *	685/80-25	22.0-25	1,715	718	236	18,295
29.5-25 *		25.0-25	1,845	761	264	22,540

* Also available as standard version

HPS SOLIDFLEX SMOOTH

Tire Size	Alternative Size	Rim Size	Overall Diameter [mm]	Section Width [mm]	Tread Depth [mm]	Load Capacity 10 km/h [kg]
17.5-25 *	445/80-25	14.0-25	1,340	446	155	8,805
20.5-25 *	525/80-25	17.0-25	1,495	527	188	12,155
23.5-25 *	605/80-25	19.5-25	1,630	606	216	15,320
26.5-25 *	685/80-25	22.0-25	1,715	718	236	18,295
29.5-25 *		25.0-25	1,845	761	264	22,540
18.00-33		13.0-33	1,831	457	216	12,000

* Also available as standard version

HPS SMOOTH

Tire Size	Alternative Size	Rim Size	Overall Diameter [mm]	Section Width [mm]	Tread Depth [mm]	Load Capacity 10 km/h [kg]
20.5-25 *	525/80-25	17.0-25	1,495	527	188	16,210
23.5-25 *	605/80-25	19.5-25	1,630	606	216	20,425
26.5-25 *	685/80-25	22.0-25	1,715	718	236	24,390
29.5-25 *		25.0-25	1,845	761	264	30,050

* Also available as standard version

Notes: Tread depth on smooth tires indicates wearable rubber.
All Brawler™ HPS tires are available as either an assembly or as tire only.



TRELLEBORG

Trelleborg Wheel Systems Italia S.p.A.
Via Nazionale Tiburtina, 143 - 00010 Villa Adriana (RM) Italy
Phone: +39 0774 384701 - Fax: +39 0774 384702
www.trelleborg.com/wheels

facebook.com/TrelleborgConstruction
youtube.com/TrelleborgConstruction

