



# EMR 1051 Earthmover Radial Tires

## PREMIUM RADIAL PNEUMATIC

The Trelleborg EMR range is designed to enhance productivity in critical construction applications, delivering both enhanced damage protection and durability. The multi surface tread design delivers control and perfect grip when it's needed the most, whether on sand, rock, gravel or soil.


The strong radial carcass and state of the art compound assure long life, while providing equal load distribution for a comfortable ride, maintaining low fuel consumption.

Designed for loaders, the EMR 1051 range is the best solution for intensive loading applications in industries such as open pits and quarries as well as infrastructure and building construction and landscaping where traction cannot be compromised.

### Main benefits

- Optimal traction
- Excellent tire life due to deep tread
- Cut resistant compound
- Sidewall rubber ring guard protection
- Robust carcass to support eventual retreading\*

### Application

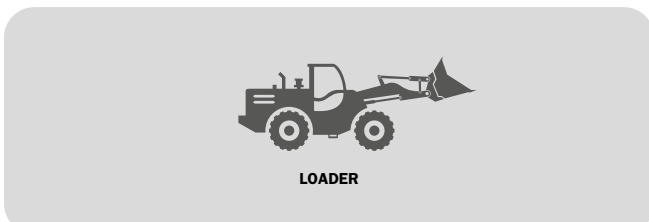

### Tire features


|                               |                    |               |                        |
|-------------------------------|--------------------|---------------|------------------------|
|                               |                    |               |                        |
| ALL-STEEL RADIAL CONSTRUCTION | REINFORCED CARCASS | MULTI SURFACE | EXCELLENT RIDE COMFORT |

\*Carcass should be checked by a professional technician before retreading is permitted

# EMR 1051

PREMIUM RADIAL PNEUMATIC

## New sidewall protection

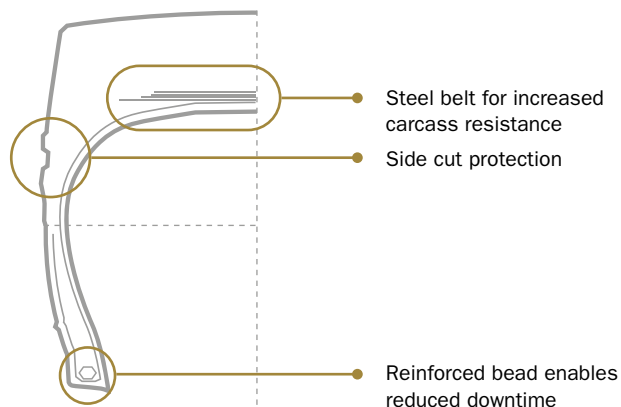

**Superior tire technology for severe applications.**

## TECHNICAL DATA – LOADER SERVICE

| Tire Size        | Tread Pattern TRA | Rim Size (Permitted)           | Tread Depth [mm] | Service Description LI/SS Loader | Tire Load Capacity (kg) 10 (km/h) | Tire Pressure (bar) |
|------------------|-------------------|--------------------------------|------------------|----------------------------------|-----------------------------------|---------------------|
| <b>20.5 R 25</b> | L5                | 17.00/2.0-25<br>(17.00/1.7-25) | 70               | **<br>193 A2                     | 11,500                            | 5.75                |
| <b>23.5 R 25</b> | L5                | 19.50/2.5-25                   | 76               | **<br>201 A2                     | 14,500                            | 5.75                |
| <b>26.5 R 25</b> | L5                | 22.00/3.0-25                   | 85               | **<br>209 A2                     | 18,500                            | 5.75                |
| <b>29.5 R 25</b> | L5                | 25.00/3.5-25                   | 92               | **<br>216 A2                     | 22,400                            | 5.75                |

\*/\*\* - Index of tire strength



**TRELLEBORG**

Trelleborg Wheel Systems Italia S.p.A.  
Via Nazionale Tiburtina, 143 - 00010 Villa Adriana (RM) Italy  
Phone: +39 0774 384701 - Fax: +39 0774 384702  
[www.trelleborg.com/wheels](http://www.trelleborg.com/wheels)

[facebook.com/TrelleborgConstruction](https://facebook.com/TrelleborgConstruction)  
[youtube.com/TrelleborgConstruction](https://youtube.com/TrelleborgConstruction)



Download the App for free



Tire iBrochure