

# TM3000

## VF750/50R26 169D

## VF1000/50R25 184D

## VF1050/50R32 198D



The new TM3000, designed with **TM<sup>BLUE</sup>** Technology, is Trelleborg's answer to the high demanding scenario of spreader machines. The VF sizes are able to satisfy the need of carrying high load capacity while limiting soil compaction during spreading operations.

### KEY PRODUCT FEATURES

Higher number of lugs vs main competitors available in the market, improving wear

Rounded shoulder for maximum soil respect


Innovative tread design to optimize ride and comfort

ProgressiveTraction™ design boosting traction and optimizing tire wear

Interlug terraces enhancing self-cleaning capacity

VF technology allows tire to carry up to 40% more load at the same pressure or to inflate the tire with 40% less pressure while carrying the same load



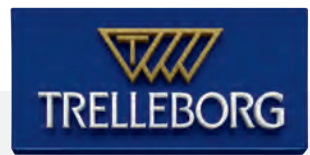

SIZE	TREAD PATTERN	SW inch	OD inch	SLR inch	RC inch	SRI	RIM	PERMITTED RIMS	TYPE	TUBE
VF750/50R26 169D	TM3000	29.5	55.7	24.2	166.5	675	DW27B	DW25B	Tubeless	
Footprint Area inch <sup>2</sup>		Tread Depth 50/32				Weight lb 455.77				
SPEED	PRESSURE									
	psi	14	17	20	23	26	29	32	35	
	bar	1.0	1.2	1.4	1.6	1.8	2.0	2.2	2.4	
MAX. LOAD lbs										
Up to 40 mph (*)		7680	8640	9600	10560	11170	11720	12210	12790	
Field Service (*)		7680	8640	9600	10560	11170	11720	12210	12790	

SIZE	TREAD PATTERN	SW inch	OD inch	SLR inch	RC inch	SRI	RIM	PERMITTED RIMS	TYPE	TUBE
VF1000/50R25 184D	TM3000	40.6	64.6		191.7	775	36.0 TH		Tubeless	
Footprint Area inch <sup>2</sup>		Tread Depth 60/32				Weight lb 807.03				
SPEED	PRESSURE									
	psi	14	17	20	23	26	29	32	35	
	bar	1.0	1.2	1.4	1.6	1.8	2.0	2.2	2.4	
MAX. LOAD lbs										
Up to 40 mph (*)		12100	13490	15080	16470	17460	18450	19150	19840	
Field Service (*)		12100	13490	15080	16470	17460	18450	19150	19840	

SIZE	TREAD PATTERN	SW inch	OD inch	SLR inch	RC inch	SRI	RIM	PERMITTED RIMS	TYPE	TUBE
VF1050/50R32 198D	TM3000	40.7	73.2	32.3	219.3	875	36.00 VA		Tubeless	
Footprint Area inch <sup>2</sup>		Tread Depth 55/32				Weight lb 943.3				
SPEED	PRESSURE									
	psi	14	17	23	29	35	41	46	52	
	bar	1.0	1.2	1.6	2.0	2.4	2.8	3.2	3.6	
MAX. LOAD lbs										
Up to 40 mph (*)		14330	16170	19840	22050	23370	26010	27560	29100	
Field Service (*)		14330	16170	19840	22050	23370	26010	27560	29100	



WWW.TRELLEBORG.COM/WHEELS/US

Trelleborg Wheel Systems Americas, Inc  
570 Trelleborg Drive, Spartanburg, SC 29301  
Toll Free Phone Number: 1-866-633-8473