

TM2000. Productivity at first sight.



Download the App for free


Tire iBrochure

TM2000

The latest radial tyre generation for harvesting machines is the result of the most advanced technology and Trelleborg experience in agricultural tyres.

High load capacity assured by a strong carcass and by a large lug width.

Robust radial construction for the maximum reliability in all working condition.

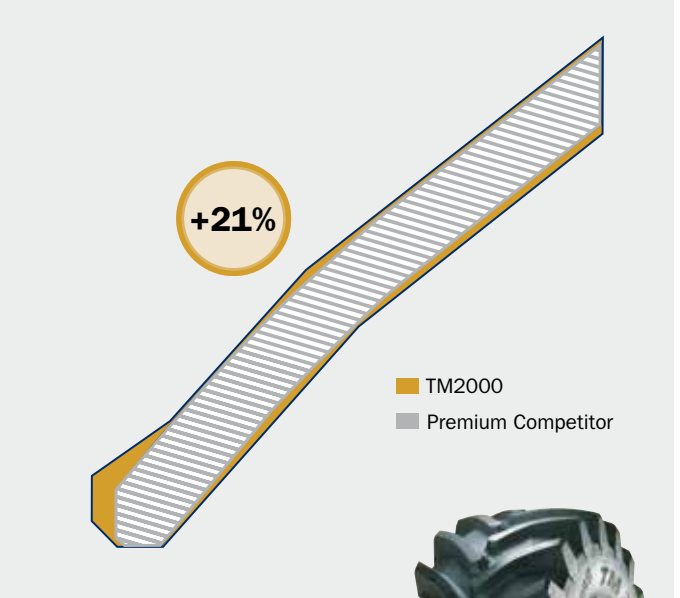

SIZE	Tread Pattern	SW mm	OD mm	SLR mm	RC mm	SRI	Rim	Permitted Rims	Type	Tube
620/75R26 166A8 (23.1R26)	TM2000	633	1590	716	4850	750	DW20B		TUBELESS	
650/75R32 172A8 (24.5R32)	TM2000	662	1817	805	5495	825	DW20B		TUBELESS	24.5-32
710/75R32 177A8	TM2000	735	1850	830	5595	875	DW23B		TUBELESS	30.5-32
800/65R32 178A8 (30.5LR32)	TM2000	800	1846	829	5595	875	DW27B	DW25B - DH27 - DW28B	TUBELESS	30.5-32
900/60R32 181A8	TM2000	890	1900	855	5765	925	DW30B	DW27B - DW28B	TUBELESS	30.5-32



TRELLEBORG

Trelleborg South Africa Pty Ltd
 Old Heidelberg Road, C/O Nederveen Highway and Philips Road
 Phone: 011 865-3110 – Fax: 011 865-2965
 Email: TWS.SA.Info@trelleborg.com
 www.trelleborg.com/wheels/za

