

TM2000. Enrich your farming.



Download the App for free




Tire iBrochure

TM2000

Radial tire for harvesting machines, result of the most advanced technology of Trelleborg experience in agricultural tires.

High load capacity assured by a strong carcass and by a large lug width.

Robust radial construction for the maximum reliability in all working condition.

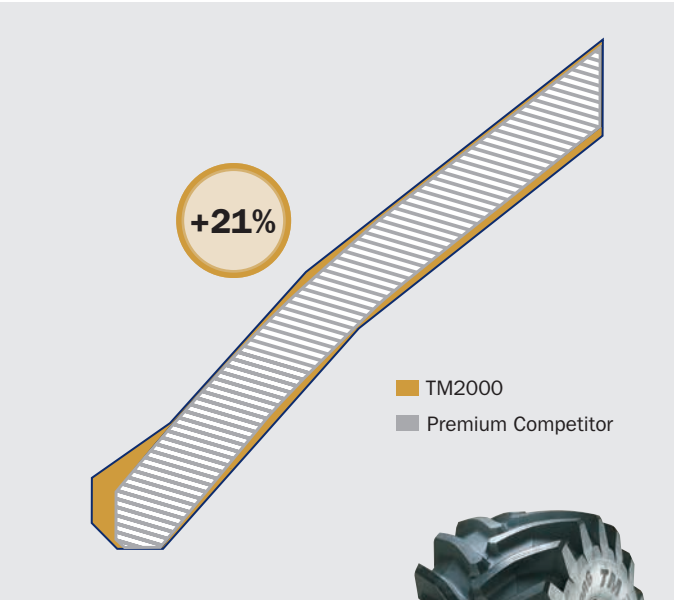

SIZE	Tread Pattern	SW mm	OD mm	SLR mm	RC mm	SRI	Rim	Permitted Rims	Type	Tube
620/75R26 166A8 (23.1R26)	TM2000	633	1590	716	4850	750	DW20B		TUBELESS	
650/75R32 172A8 (24.5R32)	TM2000	662	1817	805	5495	825	DW20B		TUBELESS	24.5-32
710/75R32 177A8	TM2000	735	1850	830	5595	875	DW23B	DW21B	TUBELESS	30.5-32
800/65R32 178A8 (30.5LR32)	TM2000	800	1846	829	5595	875	DW27B	DW25B - DH27 - DW28B	TUBELESS	30.5-32
900/60R32 181A8	TM2000	890	1900	855	5765	925	DW30B	DW27B - DW28B	TUBELESS	30.5-32



TRELLEBORG

Trelleborg Wheel Systems Italia S.p.A.
Via Nazionale Tiburtina, 143 - 00010 Villa Adriana (RM) Italy
Phone: +39 0774 384701 - Fax: +39 0774 384702
www.trelleborg.com/wheels

