


Binnenbanden STT

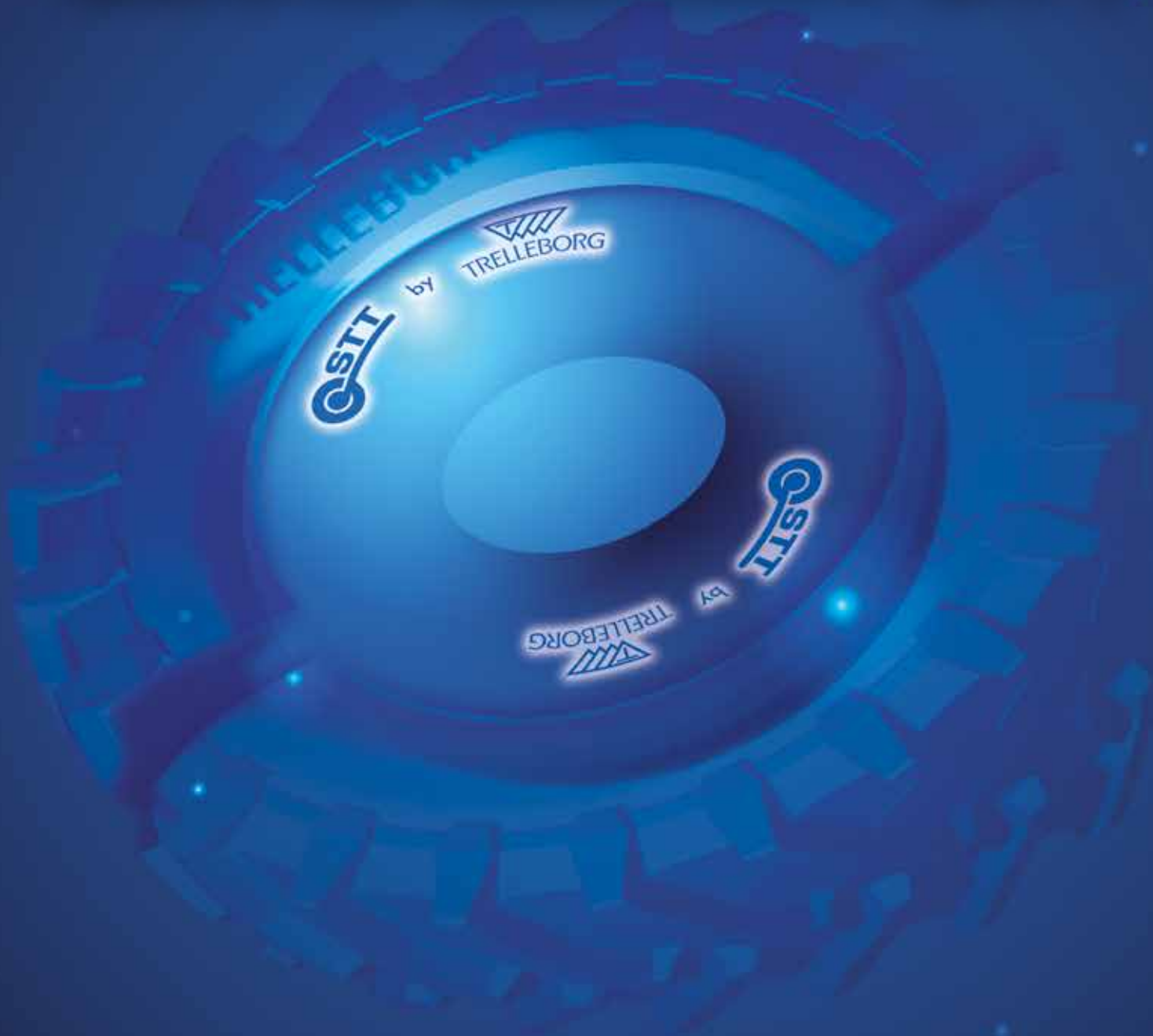

	BANDENMAAT	TYPE VENTIEL
Ø10	ER10, 145R10 4.00/4.10/4.40-10, 4.80/5.00/5.20-10, 5.95/145-10, 5.9-10	TR13
Ø12	DR12, 125R12 4.00/4.40-12, 5.35/125-12, 5.3-12	TR13
	ER12, 135/145R12, 145/70R12, 155/70R12, 140/150R12, 4.80/5.00/5.20/5.50-12, 5.65/135-12, 5.95/145-12, 5.9-12	TR13
	FR12, 155R12 175/70R12, ZR 70-12, 5.60/6.00-12, 12,6-12, 6.2-12	TR13
Ø13	ER13, 135/145R13, 145/70R13, 155/70R13, 140/150R13, 165/70R13, 5.20/5.50-13, 5.65/135-13, 5.95/145-13, 5.9-13	TR13
	FR13, 155/165R13, 175/70R13, 160R13, 5.60/5.90/6.00-13, 6.15/155-13, 6.45/165-13, A78-13, Y78-13, 6.2-13, 6.9-13	TR13
	GR13, 175/185R13, 185/70R13, 195/70R13, 205/70R13, 170/180R13, CR70-13, BR70-13, 6.40/6.50, 6.70/7.00-13, 6.95/175-13, 7.35/185-13, B78-13, C78-13, 7.3-13	TR13
Ø14	ER14, 135/145R14, 145/70R14 155/70R14, 165/70R14, 140/150R14, 5.00/5.20/5.50-14, 5.65/135-14, 5.95/145-14	TR13
	FR14, 155/165R14, 175/70R14, 185/70R14, 160R14, CR78-14, 5.60/5.90/6.00-14, 6.15/155-14, 6.45/165-14, 6.2-14, 6.9-14	TR13
	GR14, 175/185R14, 195/70R14, 170/180R14, 6.40/6.50/6.70/7.00-14, 6.95/175-14, 7.35/185-14, C78-14, D78-14, 7.3-14	TR13
	KR14, 195/205R14, 205/70R14, 215/70R14, DR70-14, ER70-14, FR70-14, 7.50/8.00-14, 7.75/195-14, 8.25/205-14, E78-14, F78-14	TR13
Ø15	DR15, 125R15 4.00/4.25/4.40-15	TR13
	ER15, 135/145R15, 145/70R15, 155/70R15, 140/150R15-15, 165/70R15, 5.00-15, 5.20/5.50-15, 5.65/135-15, 5.95/145-15, 6.2-15	TR13
	FR15, 155/165R15, 175/70R15, 185/80R15, 160R15, BR70, 5.60/5.90/6.00L15, 6.35/155-15, 6.85/165-15, 165x380, 6.9-15	TR13
	GR15, 175/185R15, 195/70R15, 207/70R15, 170/180R15, 690x170-15, 690x190-15, 6.40/6.50/6.70/7.00L15, 7.15/175-15, 7.35/185-15, 17x380, 7.3-15	TR13
	KR15, 195/205R15, 215/70R15, 225/70R15, GR70-15, 7.00/7.10/7.60-15, 7.75/195-15, 8.15/205-15	TR13
	MR15, 215/225R15, 235/70R15, HR70-15, GR70-15, 7.50/8.00/7.20/9.00-15, 7.60-15, 8.85/215-15	TR13
Ø16	GR16, 175/185R16	TR15
	GR16, 175/185R16	TR 13
	KR16, 195/205R16	TR15
	KR16, 195/205R16	TR 13
	MR16, 215/225R16	TR 15
	MR16, 215/225R16	TR 13

BANDENMAAT	TYPE VENTIEL
Ø15	
7.50-15	V3-02-8 (TR76)
8.15-15 (28X9-15)	V3-02-27 (TR75)
8.25-15	V3-02-26 (TR77)
Ø16	
6.50/7.00-16	V3-02-8 (TR76)
7.50-16	TR150
7.50-16	V3-02-9 (TR177)
8.25-16	V3-02-8 (TR76)
280/85-16	TR15
Ø20	
6.50/7.00R20/6.50/7.00-20	V3-02-27 (TR75)
7.50R20/7.50-20	V3-02-8 (TR76)
8.25R20/8.25-20	V3-02-26 (TR77)
9.00R20/9.00-20	V3-02-29 (TR78)
10.00R20/10.00-20	V3-02-29 (TR78)
11.00R20/11.00-20	V3-02-15 (TR179)
12.00R20/12.00-20	V3-02-15 (TR179)
13.00R20/13.00-20	V3-02-15 (TR179)
14.00R20/14.00-20	V3-02-15 (TR179)
Ø24	
12.00R24/12.00-24	V3-02-15 (TR179)
13.00-24	TR220