


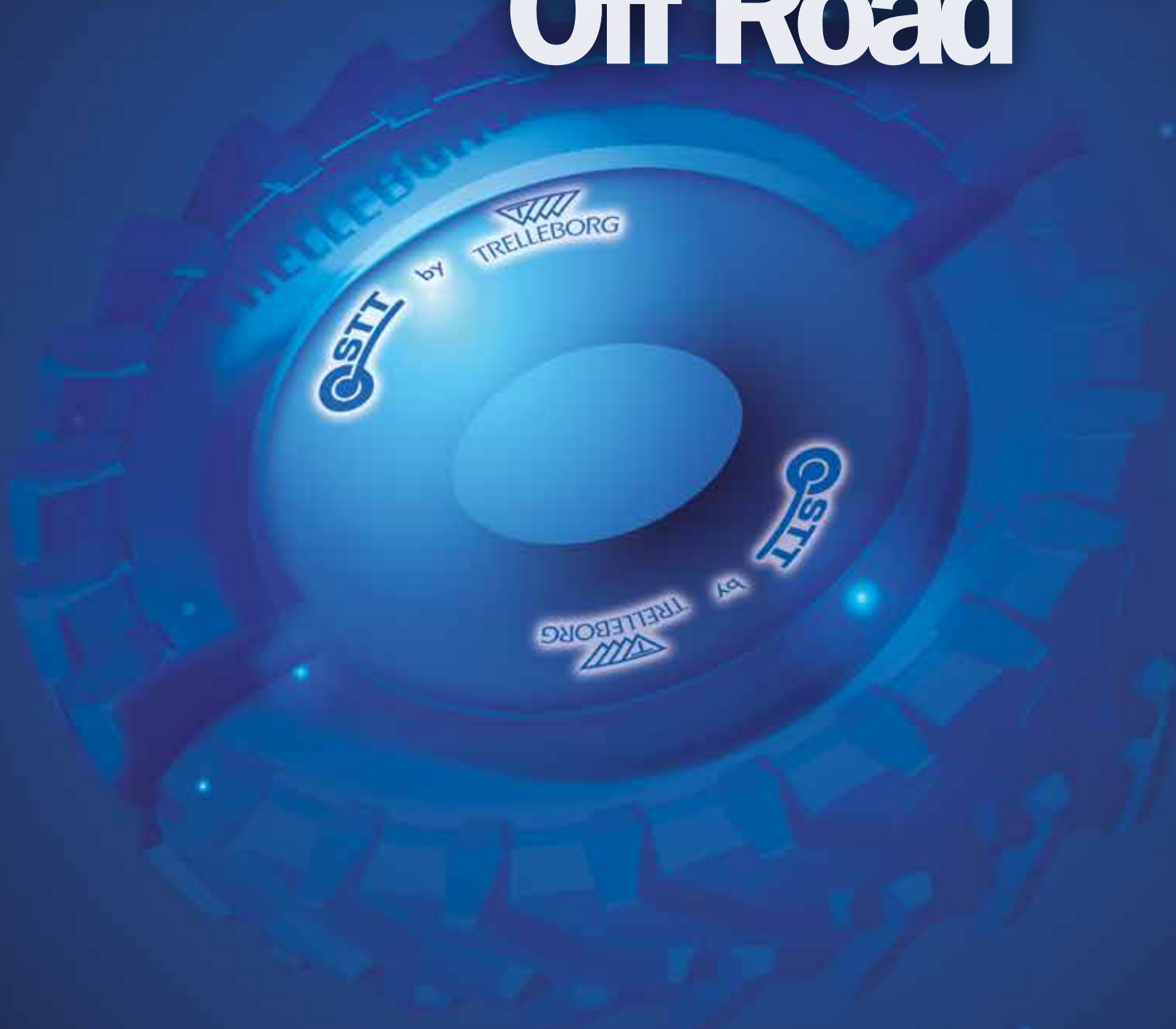

Binnenbanden STT Off Road



	BANDENMAAT	TYPE VENTIEL
Ø25		
	14.00-24/25	TR220
	14.00-24/25	V3-02-15 (TR179)
	14.00-24/25	TRJ1175
	16.00-24/25	TRJ1175
	18.00-24/25	TRJ1175
	15.5-25	TRJ1175
	17.5-25	TRJ1175
	17.5-25	TRJ4000
	20.5-25	TRJ1175
	20.5-25	TRJ4000
	23.5-25	TRJ1175
	23.5-25	TRJ4000
	26.5-25	TRJ1175