

# TM2000. Productivity at first sight.




# TM2000

The latest radial tire generation for harvesting machines is the result of the most advanced technology and Trelleborg experience in agricultural tires.

High load capacity assured by a strong casing and by a large lug width.

Robust radial construction for the maximum reliability in all working condition.

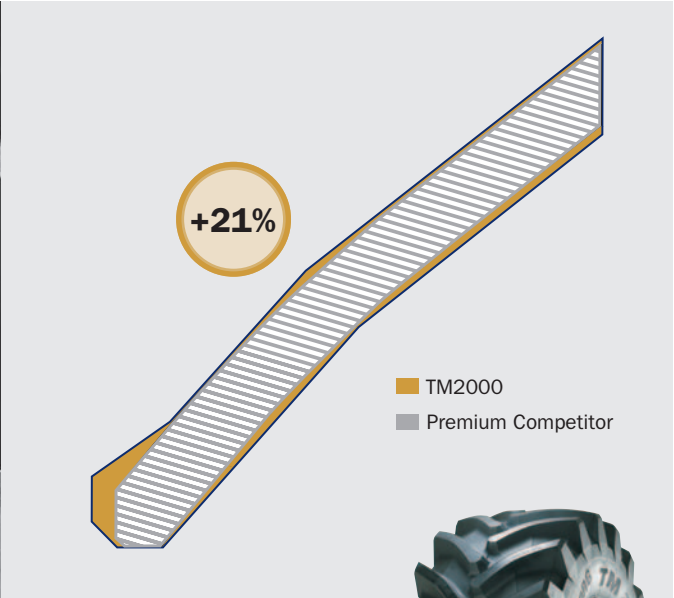

SIZE	Tread Pattern	SW Inches	OD Inches	SLR Inches	RC Inches	SRI	Rim	Permitted Rims	Type	Tube
<b>620/75R26</b> 166A8 (23.1R26)	<b>TM2000</b>	24.9	62.6	28.2	190.9	750	DW20B		TUBELESS	
<b>650/75R32</b> 172A8 (24.5R32)	<b>TM2000</b>	26.1	71.5	31.7	216.3	825	DW20B		TUBELESS	24.5-32
<b>710/75R32</b> 177A8	<b>TM2000</b>	28.9	72.8	32.7	220.3	875	DW23B		TUBELESS	30.5-32
<b>800/65R32</b> 178A8 (30.5LR32)	<b>TM2000</b>	31.5	72.7	32.6	220.3	875	DW27B	DW25B - DH27 - DW28B	TUBELESS	30.5-32
<b>900/60R32</b> 181A8	<b>TM2000</b>	35	74.8	33.7	227	925	DW30B	DW27B - DW28B	TUBELESS	30.5-32



**TRELLEBORG**

Trelleborg Wheel Systems Americas, Inc.  
Toll Free Phone Number: 1-866-633-8473  
[www.trelleborg.com/wheelsystems/us](http://www.trelleborg.com/wheelsystems/us)

