



# Road bridge Expansion Joint Transflex 3600-6400

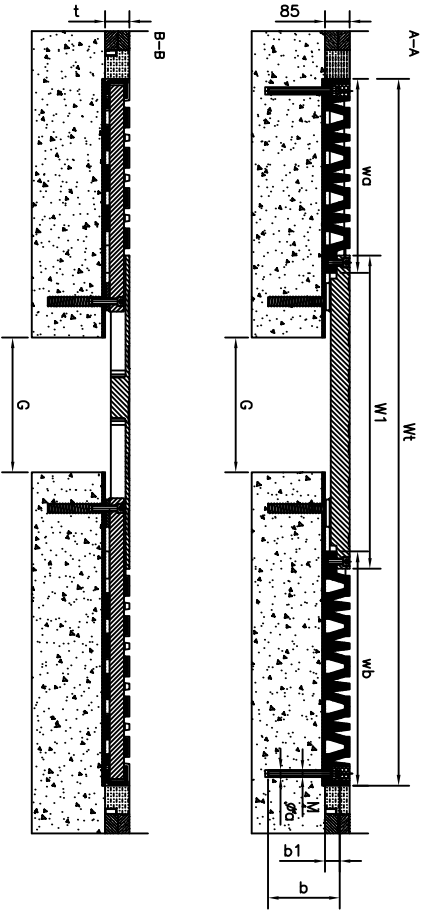

Whilst all reasonable care is taken in compiling technical data on the company's products, some changes might take place with no responsibility for Trelleborg Izarra. Also all recommendations or suggestions regarding the use of any products are made without guarantee since the conditions of use are beyond the control of the company. It is the customer's responsibility to satisfy himself that each product is fit for the purpose for which he intends to use it and that the actual conditions of use are suitable.

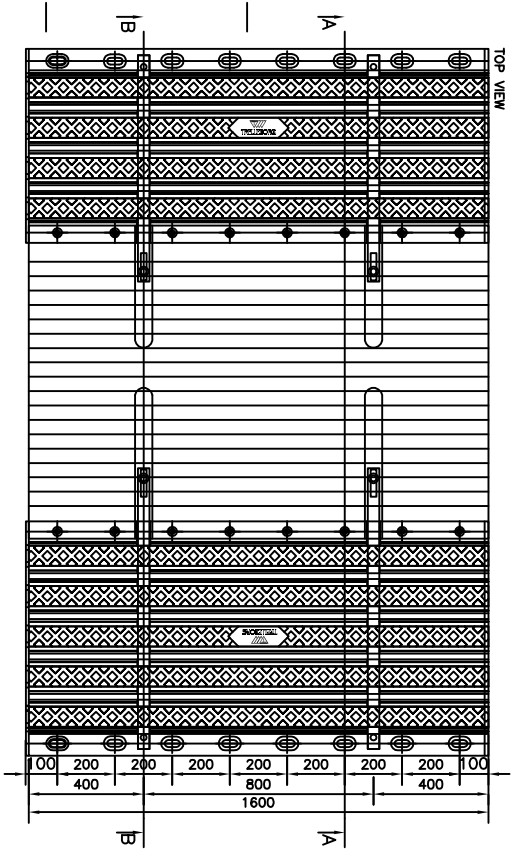

Module	Movement	Module												
		L	H	W	W1	W2	Wb	Wp	Wq	Wt	T			
Transflex	(mm)	1600	85	2440	1090	675	815	1050	200	470	170	M20x200	22	55
3600	900 (±450)	1600	85	2440	1090	675	815	1050	200	470	170	M20x200	22	55

Module	Movement	Module												
		L	H	W	W1	W2	Wb	Wp	Wq	Wt	T			
Transflex	(mm)	1600	85	2680	1190	815	815	1250	200	520	170	M20x200	22	55
4000	1000 (±500)	1600	85	2680	1190	815	815	1250	200	520	170	M20x200	22	55

Module	Movement	Module												
		L	H	W	W1	W2	Wb	Wp	Wq	Wt	T			
Transflex	(mm)	1600	85	2920	1280	815	955	1440	200	570	170	M20x200	22	55
4400	1100 (±550)	1600	85	2920	1280	815	955	1440	200	570	170	M20x200	22	55

Module	Movement	Module												
		L	H	W	W1	W2	Wb	Wp	Wq	Wt	T			
Transflex	(mm)	1600	85	3160	1380	955	955	1630	200	620	170	M20x200	22	55
4800	1200 (±600)	1600	85	3160	1380	955	955	1630	200	620	170	M20x200	22	55

Module	Movement	Module												
		L	H	W	W1	W2	Wb	Wp	Wq	Wt	T			
Transflex	(mm)	1600	85	3400	1490	955	1095	1850	200	670	170	M20x200	22	55
5200	1300 (±650)	1600	85	3400	1490	955	1095	1850	200	670	170	M20x200	22	55

Module	Movement	Module												
		L	H	W	W1	W2	Wb	Wp	Wq	Wt	T			
Transflex	(mm)	1600	85	3640	1590	1095	1095	1980	200	720	170	M20x200	22	55
5600	1400 (±700)	1600	85	3640	1590	1095	1095	1980	200	720	170	M20x200	22	55

Module	Movement	Module												
		L	H	W	W1	W2	Wb	Wp	Wq	Wt	T			
Transflex	(mm)	1600	85	3880	1690	1095	1235	2165	200	770	170	M20x200	22	55
6000	1500 (±750)	1600	85	3880	1690	1095	1235	2165	200	770	170	M20x200	22	55

Module	Movement	Module												
		L	H	W	W1	W2	Wb	Wp	Wq	Wt	T			
Transflex	(mm)	1600	85	4120	1790	1235	1235	2350	200	820	170	M20x200	22	55
6400	1600 (±800)	1600	85	4120	1790	1235	1235	2350	200	820	170	M20x200	22	55

THIS DRAWING REMAINS THE PROPERTY OF Trelleborg IESA, s.a. AND NOT BE REPRODUCED OR IMPROPERLY USED OR COMMUNICATED TO A THIRD PARTY WITHOUT OUR WRITTEN CONSENT IN EACH CASE.

Trelleborg IESA, s.a.  
c/ San Vicente,25 -E 01440 Izarra (Alava) - Spain - Tel: +34 945 437 090 - Fax: +34 945 437 050  
Internet : www.trelleborgiesa.com - R. Mercantil de Alava. Tomo 771. Folio 208. Hoja VI-5303 Insc. 1ª A-01241744



DRAWN	REVISED	APPROVED	DATE
J.E.I.	J.E.I.	I.I.	01/2016
SCALE: S/E			

Trelleborg Izarra, s.a.  
Expandite Division  
c/Sierra de Algodonales 12-14  
+28.500 Aranda del Rey (Madrid) - Spain  
Tel: +34 91 870 17 00 - Fax: +34 91 870 34 65  
expandite@trelleborg.com

REF. DRAW	REV	SHEET
Transflex 3600-6400		OF